

Laboratory sample label guide

Brady offers durable identification labels for any laboratory sample. The labels are engineered to stay attached and remain legible in the most challenging laboratory conditions when printed with Brady printers.

Cryo vial identification



B-490, B-492

FreezerBondz™ ultra-thin polyester label to label both frozen* and room temperature vials, tubes and canes. Superior chemical and abrasion resistance.

Withstands:



*To identify an already frozen vial the label must be used with an overlap.

Tissue cassette identification



B-482

Polyester label with superior resistance to tissue processing chemicals and embedding procedures. Use with the BSP31 Label Attachment system for pre-process tissue cassette identification.

Withstands:



Tube & glass vial identification



B-461

Ultra-thin polyester label with clear tail that protects print & allows liquid levels to be viewed.

Withstands:



*Suitable for liquid nitrogen application if material is wrapped around itself, as in self-lamination.



B-7425


Polypropylene label with moderate chemical resistance, ideal for labelling dry, room temperature specimen containers.

This label is also available in a sterilisation indicating version.

Withstands:



Dish / bottle identification

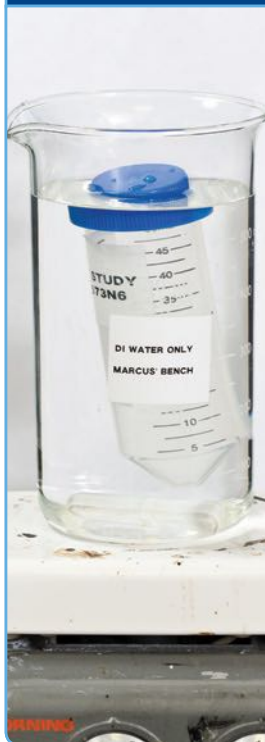

B-499 (Permanent)

Thick nylon cloth label for easy handling and conformability.

Withstands:



B-403 (Dissolvable)

water dissolvable paper label dissolves completely within 30 seconds exposure to warm water without damaging the surface or leaving sticky residue

Withstands:



B-533 (Removable)

Removable polyester, label for applications requiring clean removal.

Withstands:



Slide identification




B-481

StainerBonz™ polyester label for extreme chemical resistance and performance in slide staining processes.

Withstands:



General purpose identification

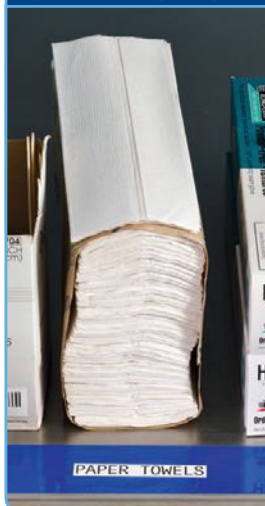

B-423

Highly adhesive white label for drawers, shelves, cabinets and general labelling.

Withstands:



B-595

Highly adhesive label for drawers, shelves, cabinets and general labelling. Available in white, red, yellow, green, blue, orange, black & clear.


Withstands:




Laboratory sample label printer guide

Every durable laboratory sample identification label can be printed in your laboratory using professional Brady Label Printers* and label software. Stop losing samples due to labels that fall off, or become illegible.

BMP21-LAB Label Printer €



Volume per day: 75 Labels
Works with LIMS: No
Works with Brady Workstation: No
Prints labels up to: 19.00mm



2 YEAR WARRANTY
 SYMBOLS

BBP12 Label Printer €€




Volume per day: 500 Labels
Works with LIMS: Yes
Works with Brady Workstation: Yes
Prints labels up to: 112mm




1 YEAR WARRANTY
 SYMBOLS

BMP51 Label Printer €€




Volume per day: 500 labels
Works with LIMS: Yes
Works with Brady Workstation: Yes
Prints labels up to: 38.10mm




2 YEAR WARRANTY
 SYMBOLS

BradyJet J2000 Colour Label Printer €€€




Volume per day: 3000 Labels
Works with LIMS: Yes
Works with Brady Workstation: Yes
Prints labels up to: 101.60mm




1 YEAR WARRANTY
 SYMBOLS

BradyPrinter M611 €€




Volume per day: 750 labels
Works with LIMS: Yes
Works with Brady Workstation: Yes
Prints labels up to: 50.80mm



2 YEAR WARRANTY
 SYMBOLS

BradyPrinter i3300 €€€




Volume per day: 1000 Labels
Works with LIMS: Yes
Works with Brady Workstation: Yes
Prints labels up to: 101.60mm




1 YEAR WARRANTY
 SYMBOLS

BMP71 Label Printer €€€




Volume per day: 1000 Labels
Works with LIMS: Yes
Works with Brady Workstation: Yes
Prints labels up to: 50.80mm




2 YEAR WARRANTY
 SYMBOLS

BradyPrinter i5100 €€€€



Volume per day: 5000 Labels
Works with LIMS: Yes
Works with Brady Workstation: Yes
Prints labels up to: 105.70mm



2 YEAR WARRANTY
 SYMBOLS

*Some laboratory sample labels are available on specific printers only.